

#4132 - Twin OFC Loudspeaker Cable 2.5mm2, 25m reels



Part NO: #4132

Product Code: RGW-1883

Product Description

Reference Standard

Customer's sample spec.and the general standard

Multi-construction

2Cores

Cable Construction

Conductor	Bare Copper
Construction	0.1 ± 0.008 x 46x 7
Standard Dia.(mm)	2.4
Insulation	Trans PVC
Thickness	0.55
Insulation Dia.(mm)	3.5 ± 0.1 x 2C
Insulation Color	Trans PVC

Marking

Colour Stripe (Black) on one side for identification

PACKAGING

100M/Reel

RoHS GUIDELINE


We operate according to the following standards

Control Item	Standard	Testing Method	Testing Equipment
Cadmium content (Cd)	<0.01%	EN1122	ICP-AES
Lead content (Pb)	<0.1%	EPA3050B	ICP-AES
Mercury content (Hg)	<0.1%	EPA3052	ICP-AES
Chromium (VI) content	<0.1%	EPA 3060(UN-VIS)	ICP-AES
Polybrominated Biphenyls(PBB)	Forbidden	GC/MS	
Polybrominated Diphenyl Ether (PBDE)	Forbidden	GC/MC	

Revision History

A0-1

Design

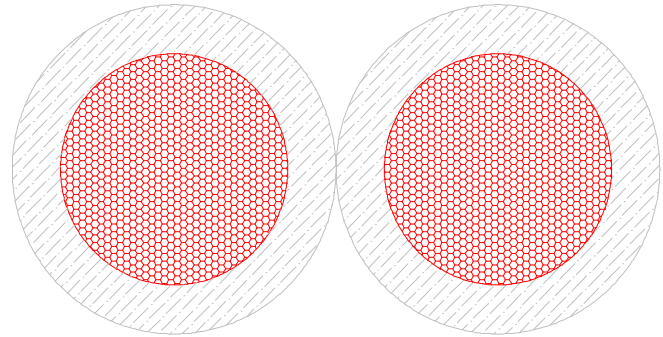

A: Electrical Characteristics

Max.Conductor DC Resistance at 20°C (Ω /Km)	<7.36
Min.Insulation DC Resistance at 20°C (MΩ *Km)	>200
Rated Temperature(°C)	80
Rated Voltage (V)	300
Capacitance (pF/m)	40 +/- 5
Inductance	0.50μH/m

Date: 2013-03-06

Page: 1 / 1