



# Datasheet

## DC Axial Fan

RS Stock number 619-6551

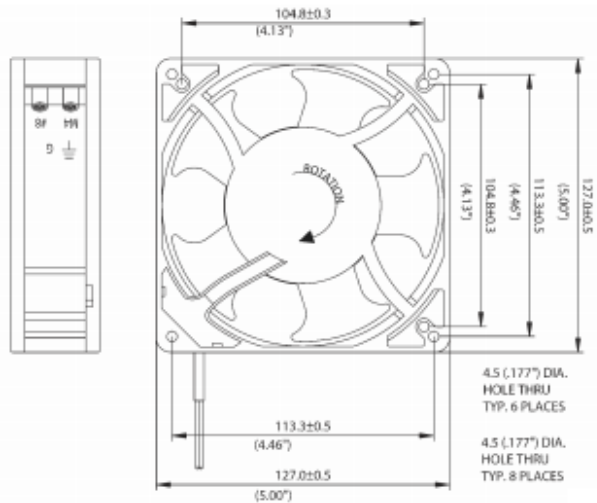

### Specification

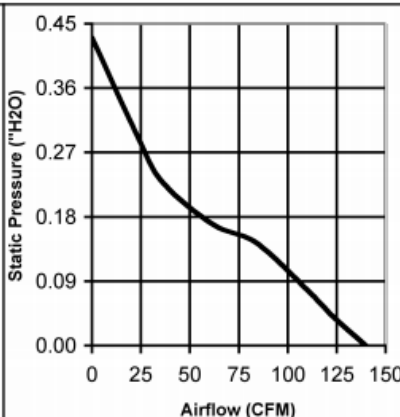Frame	Diecast Aluminum	<b>Options:</b> Tachometer - Open Collector  Conformal Coat  <u>Life Expectancy (L10)</u> Ball - 60,000 hrs (45C)  <u>Operating Temperature</u> Ball: -20 ~ 80C	
Impeller	PBT, UL94V-O plastic		
Connection	2x Lead wires, 300mm (~12")		
Motor	Brushless DC, auto restart, polarity protected		
Bearing System	Dual Ball bearing		
Insulation Resistance	10M ohm between leadwire and frame (500VDC)		
Dielectric Strength	1 min at 500 VAC, max leakage - 500 MicroAmp		
Storage Temperature	-30C ~ +90C		