


Datasheet


34 Way IDC Bump Polarised Socket, 1A

RS Stock number [625-7280](#)

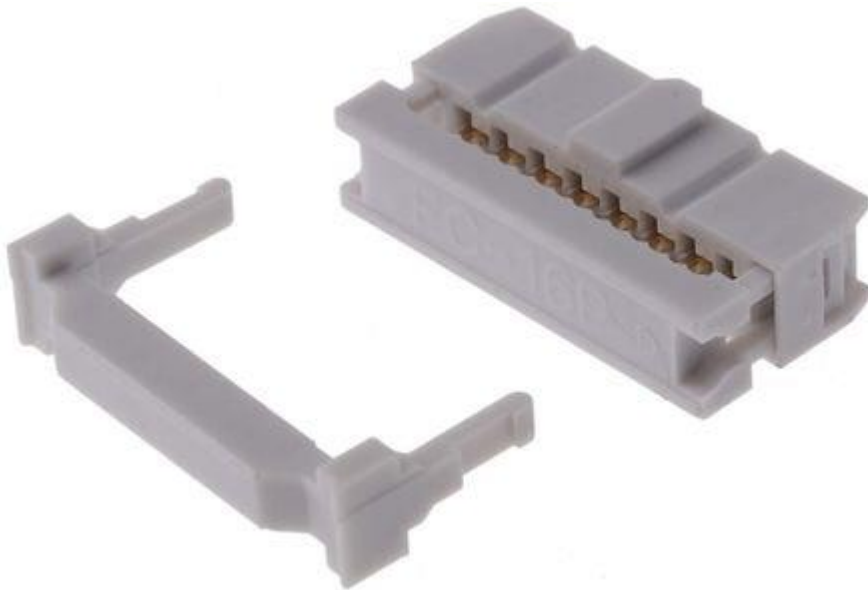

Specifications:

Current Rating:	1 Amp
Insulator Resistance:	5000M Ω min. at dc 500V
Contact Resistance:	20M Ω max. at dc 100mA
Operating Temperature:	-55°C ~ +105°C
Housing:	30% glass filled PBT UL94V-). Colour – Grey
Contacts:	Phosphor bronze
Plating:	Selective gold plated: gold plated on mating area and nickel plated on wire cutting area. Gold plated over nickel.
Cable:	1.27mm (0.050") pitch flat cable

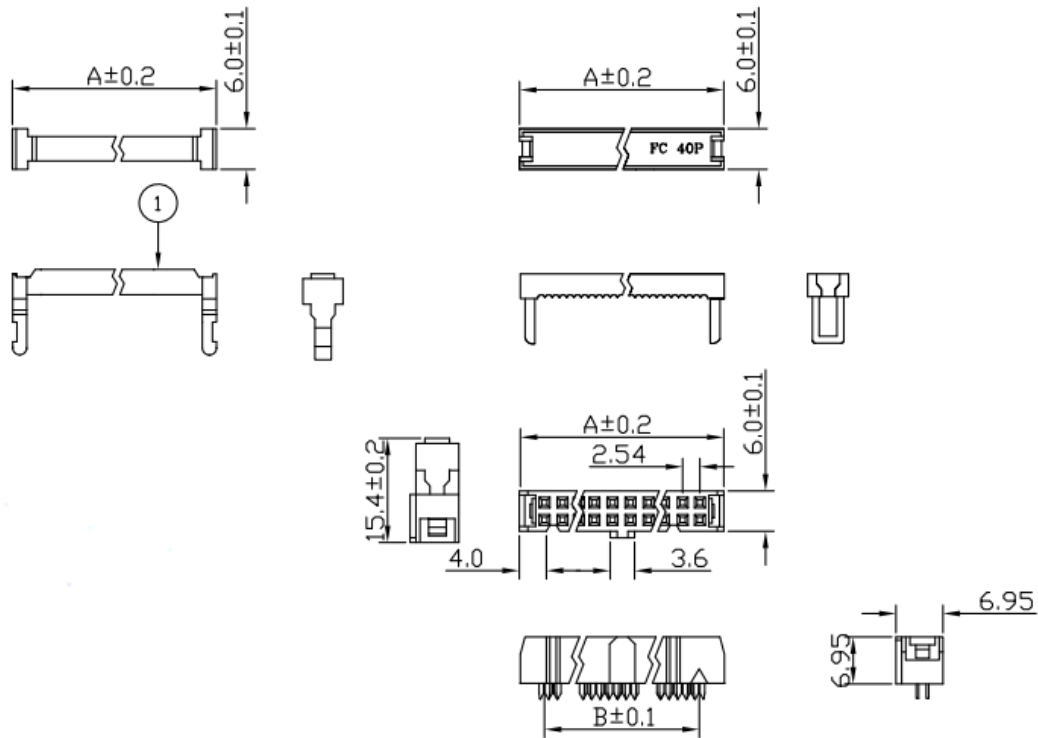

Position	Dimension	
	A	B
10	17.27	10.16
14	22.35	15.24
16	24.89	17.78
20	29.97	22.86
24	35.05	27.94
26	37.59	30.48
30	42.67	35.56
34	47.75	40.64
40	55.37	48.26
50	68.07	60.96