

Datasheet

RS Pro E10 Filament Indicator Lamp, Clear, 3.7 V, 300 mA, 10h

RS Stock No: **655-9485**



Product Details

RS Pro E10 filament indicator lamp comes with clear lens. It has a voltage rating of 3.7 V and current rating of 300 mA. The lamp has 10 h life. It is ideal for applications where a narrow beam of light is required.

Features and Benefits

- Voltage rating of 3.7 V
- Current rating of 300 mA
- 10 hours lifetime




Specifications:

Current Rating	300 mA
Diameter	10 mm
Lamp Base	E10
Length	25 mm
Lens Colour	Clear
Life Hours	10 h
Luminosity	10 lm
Voltage Rating	3.7 V

RS Stock No.

6559485

DRAWING - I

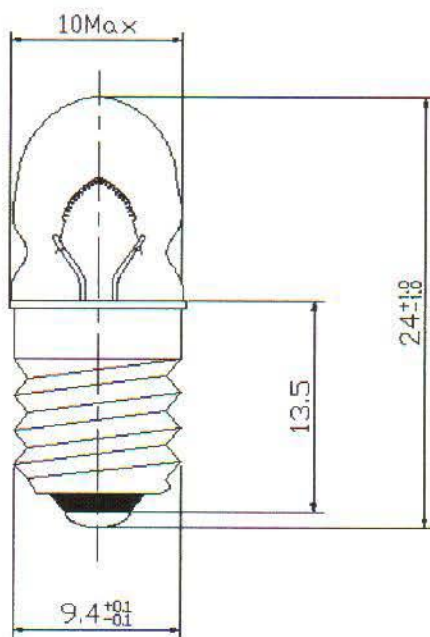

Unit : mm

1. Structure	Bulb Type	Lens Ended
	Bulb Diameter	Ø10.0Max.
	Length	25.0Max
	Base Type	E10 X 12
2. Design Characteristics	Voltage	3.7V
	Amperage	300mA± 10%
	Filament Type	Vacuum type
	Luminous Flux	10Lm± 20%
	Life Hours	10Hrs