




ENGLISH

Data Sheet

36 core screened cable,7x0.2mm 25m

RS Stock No. 660-0473

Cross Section:

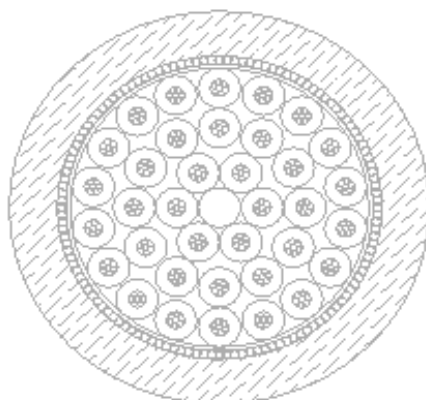

Description:

Rated Temperature (°C): -20 ~ 80

Rated Voltage (V):300

Flammability Test: IEC60332-1

Standard:

Manufacture to Def. Stan 61.12 Part 4 & 5

Construction:

Conductor:Tinned Copper

Conductor Dia. (mm): 0.20±0.008 x 7

Insulation: PVC

Insulation Dia. (mm): 1.2±0.05 x 36C

Filler: 1.2 PVC Sreip

Tape: Mylar Spiral

Coverage:≥115%

Braid Shield : Tinned Copper

Conductor Dia. (mm): 0.15

Conductor Qty: 24x9

Pitch(mm):

Coverage : 91%

ID Thread: Green, White/Green

A rip cord : 210 D

Jacket: FR-PVC

Outer Dia. (mm): 10.8±0.2

Colour:

The color of the insulation: Red , Blue , Green , Yellow , White , Balck , Brown , Violet , Orange , Pink , Light Green , Grey , Red/Blue , Green/Red , Yellow/Red , White/Red , Red/Black , Red/Brown , Yellow/Blue , White/Blue , Blue/Black , Orange/Blue , Green/Blue , Grey/Blue , Yellow/Green , White/Green , Green/Black , Orange/Green , Grey/Green , Yellow/Brown , White/Brown , Brown/Black , Grey/Brown , Yellow/Violet , Violet/Black , White/Violet

The jacket color: Black

Marking(3times/m):

RS 6600473 7 - 2 - 36C

Performance:

Electrical Characteristics:

Max.Conductor DC Resistance at 20°C (Ω/Km) : <86.2

Min.Insulation DC Resistance at 20°C (M Ω *KM) : >200

Current Rating : 1 A