


ITEM NO	COLOR	LENGTH	PE BAG	CARTON	PE LABEL
11.99.8870	WHITE	1.8M	0.06*190*300mm	K=K 1.0' 45*33*18CM Q'TY: 50PCS/CTN	8*4CM 11.99.8870 (761199018835)
11.99.8871	WHITE	3.0M	0.06*190*300mm	K=K 1.2' 44*33*22CM Q'TY: 50PCS/CTN	8*4CM 11.99.8871 (761199018836)

NOTE:

PACKING: 1PCS/PE BAG+ EAN


- CABLE:UL2725,AL+B-FOIL,(28AWG*1P)+[AL+MY-FOIL,(28AWG*1P+D)]*2+24AWG*2C.
WHITE COLOR,OD=5.5±0.2mm,PVC JACKET.
- LENGTH:L.
- CONNECTORS:USB3.0 M(A)*1PCS,USBA 3.0M(B)*1(BLUE INSULATOR)(SHELL NICKEL).
- MOLD:MOLDING USB TYPE.
- CONTACTS:

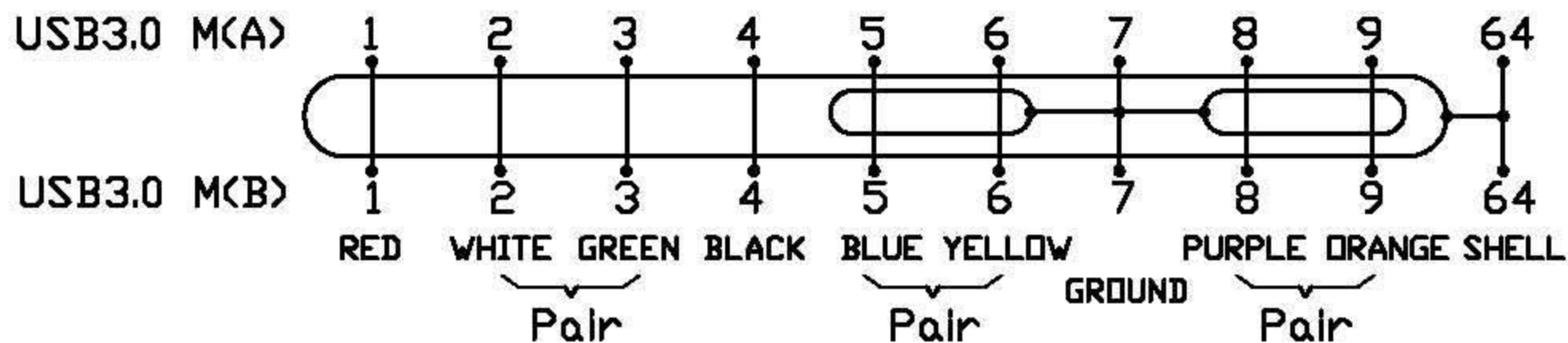

WHITE/GREEN PAIR...28AWG , RED/BLACK...24AWG

- Test machine test condition.
A.100% OPEN,SHORT&INTERMITANCE TEST.
B.CONDUCTOR RESISTANCE:3ohms MAX:
C.INSULATION RESISTANCE:5M Min/,10ms:

7. ALL MUST BE MEET ON ROHS COMPLIANT.

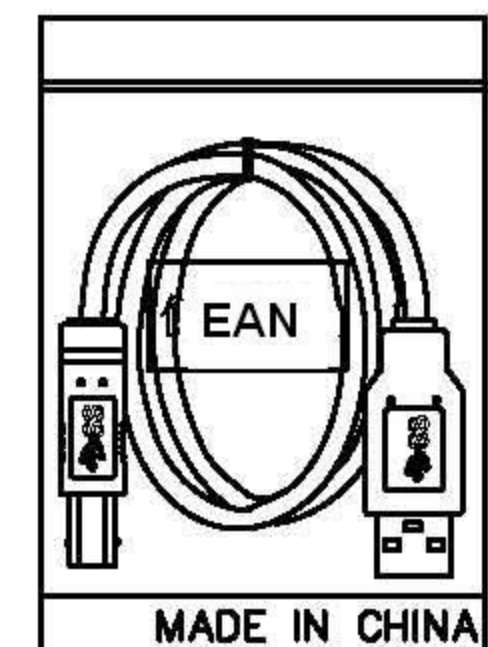

PE BAG(190*300*0.06)

REVISION	DATE	DISCRIPTION	DRAWN BY	DESIGNED BY	APPROVAL BY	VALUE	SCALE	NON
REV.A/0	2011.03.01					VALUE USB 3.0 Cable, Type A-B, white	UNIT(mm)	1/1
REV.A/1	2011.11.16				SCALE		NON	
					PAGE		1/1	

