


Datasheet

SMA-SMA plug cable assembly

RS Stock number 794-2885



Dimensions: (mm)

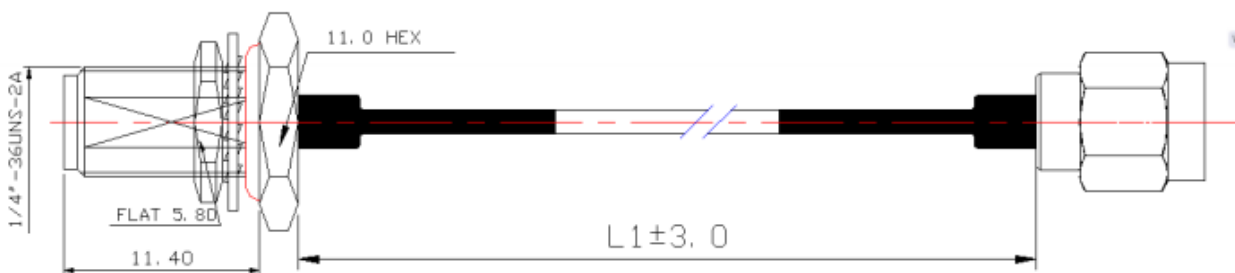


Specification

PRODUCT MATERIAL

1. SMA IP67 B/H JACK CRIMP TYPE FOR ϕ 1.37mm CABLE NUT x 1,WASHER x 1
2. SMA STRAIGHT PLUG FOR ϕ 1.37mm CABLE
3. 1.37mm CABLE TIN PLATED COLOR:BLACK
4. HEAT SHRINK TUBE F32 ϕ 2.5mm L=15.0mm COLOR:BLACK

ELECTRICAL PERFORMANCE:

- 1.IMPEDANCE:50 OHMS
- 2.FREQUENCY RANGE:DC~3GHz
- 3.WORKING VOLTAGE:250Vrms MAXIMUM
- 4.DIELECTRIC WITHSTANDING VOLTAGE:750Vrms min.

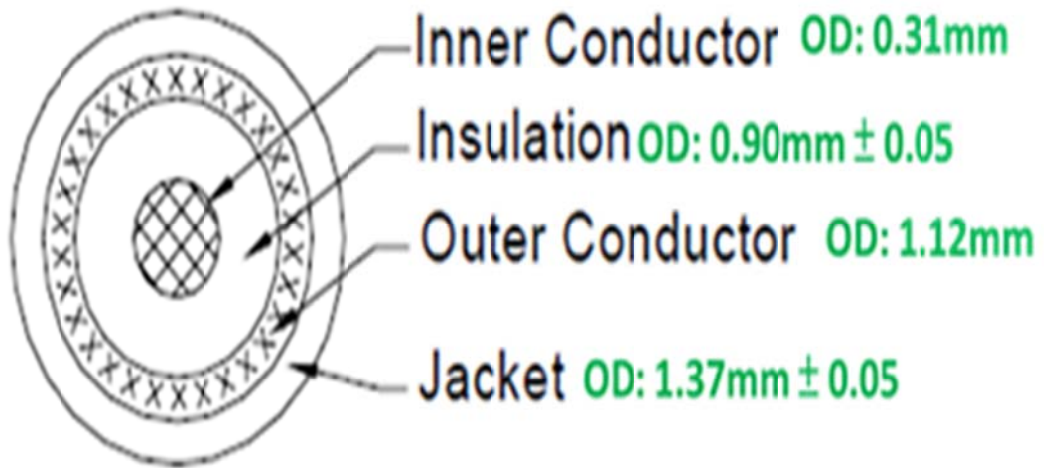

Cross-section of cable