
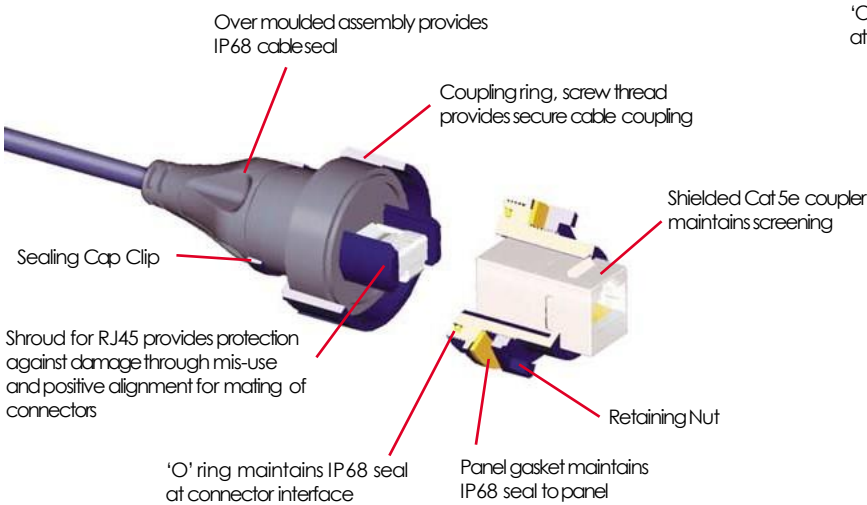


Ethernet Buccaneer®

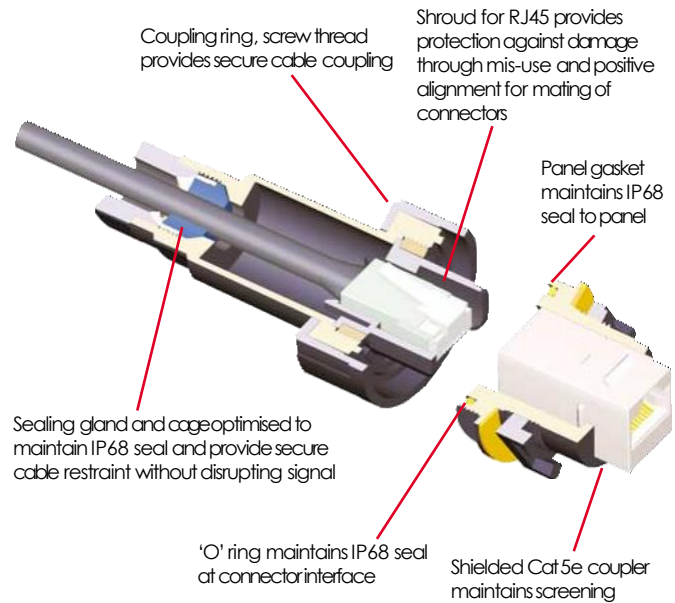

- IP68 rated
- Cat 5e compliant
- PUR jacket on cable
- Shielded system
- Cat 5e shielded coupler
- Shroud on RJ45
- Screw coupling
- Rewireable flex connector
- PCB mounted panel connector
- IDC termination panel connector
- Earth lead version of panel adaptor
- € Dust and waterproof sealing when mated
- € Data rate up to 100MHz
- € Good chemical resistance, flame retardant
- € High noise immunity and EMI protection
- € Maintains shielding
- € Protection from abuse and mis-mating
- € Secure, proven locking system
- € Ability to 'field' terminate
- € Direct PCB mount panel connector
- € Simple termination
- € Continuous screening of panel mount connector


BUCCANEER

Ethernet Buccaneer®



- Mates with panel mounting connector (PX0833, PX0839/PC & PX0839/IDC)
- Patchcards with IP68 connector
- Supplied with shielded RJ45 plug
- Single or double end terminated
- Standard lengths: 2m, 3m & 5m
- S-FTP cable construction
- PUR jacket cable
- Wiring configuration to 568-B
- Exceeds EIA/TIA Cat 5e

| Part no. | Type | Length | Description |
|-------------|----------|--------|-------------------------------|
| PX0836/2M00 | Wire end | 2m | IP68 RJ Buccaneer to bare end |

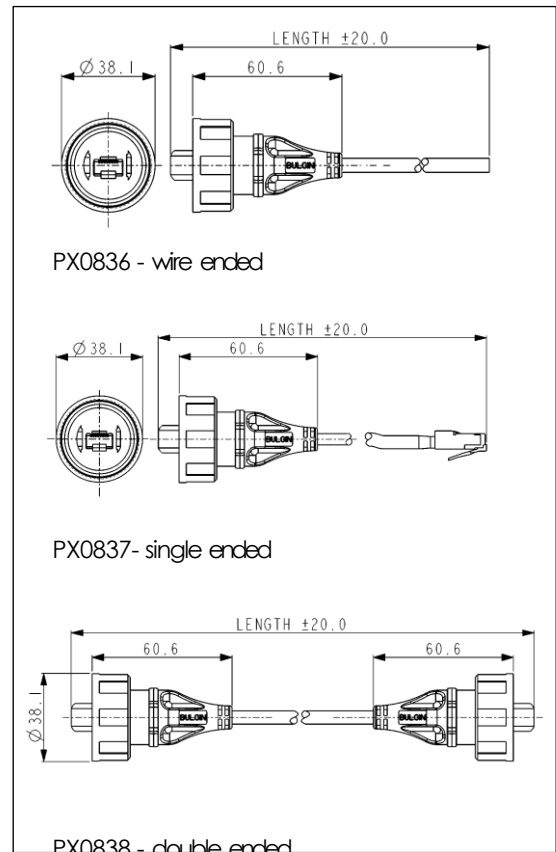

BUCCANEER