

{ IMPROVE } PRODUCTIVITY


SQUIDS® TIE HOOK SERIES

HI VIS ORANGE COLOR | TEMP RANGE: -40°F - 176°F (-40°C - 80°C) | PATENT PENDING

3510 Tie Hook - Small Hook

Super duty, reusable tie hook for organizing and cinching hoses, cords, pipe and almost anything else.

- Small hook attachment with 360° swivel (1.2"/30mm)
- Adjustable sliding belt lock mechanism
- High tensile strength, weather resistant Nylon 66
- Excellent resistance to oil, salt, solvents, and alkali
- Temp range: -40°F - 176°F (-40°C - 80°C)
- Recommended load limit: 22 lbs. (10kg)
- 3510S: 11.8" (30cm) belt
- 3510M: 15.8" (40cm) belt
- 3510L: 19.7" (50cm) belt

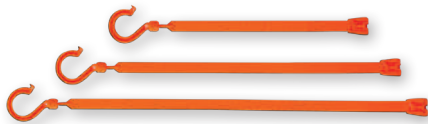

3530 Tie Hook - Large Hook

Super duty, reusable tie hook for organizing and cinching hoses, cords, pipe and almost anything else.

- Large hook attachment with 360° swivel (2"/50mm)
- Adjustable sliding belt lock mechanism
- High tensile strength, weather resistant Nylon 66
- Excellent resistance to oil, salt, solvents, and alkali
- Temp range: -40°F - 176°F (-40°C - 80°C)
- Recommended load limit: 22 lbs. (10kg)
- 3530S: 11.8" (30cm) belt
- 3530M: 15.8" (40cm) belt
- 3530L: 19.7" (50cm) belt



3540 Tie Hook - Large Locking Hook

Super duty, reusable tie hook for organizing and cinching hoses, cords, pipe and almost anything else.


- Large hook attachment with 360° swivel (2"/50mm)
- Cable lock for security and increased load capacity
- Adjustable sliding belt lock mechanism
- High tensile strength, weather resistant Nylon 66
- Excellent resistance to oil, salt, solvents, and alkali
- Recommended load limit: 44 lbs. (20kg)
- 3540S: 11.8" (30cm) belt
- 3540M: 15.8" (40cm) belt
- 3540L: 19.7" (50cm) belt



3560 Tie Hook - Hand Grip

Super duty, reusable tie hook for toting and organizing hoses, cords, pipe and almost anything else.

- Large hand grip with 360° swivel (40x95mm/1.6x3.7")
- Grip opens to lock around anchor point
- Adjustable sliding belt lock mechanism
- High tensile strength, weather resistant Nylon 66
- Excellent resistance to oil, salt, solvents, and alkali
- Recommended load limit: 44 lbs. (20kg)
- 3560M: 15.8 inch (40cm) belt
- 3560L: 19.7 inch (50cm) belt

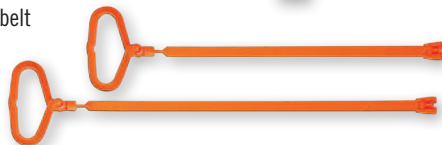

3580 Tie Hook - Double Belt w/Connecting Joint

Super duty, reusable belts for tight cinching and max load capacity.

- Connecting joint with 360° swivel
- Double belt cinches on both ends
- Adjustable sliding belt lock mechanism
- High tensile strength, weather resistant Nylon 66
- Excellent resistance to oil, salt, solvents, and alkali
- Recommended load limit: 55 lbs. (25kg)
- 3580M: 15.8 inch (40cm) belt
- 3580L: 19.7 inch (50cm) belt







{ IMPROVE } PRODUCTIVITY

USING SQUIDS® TIE HOOKS


These 'roided up zip ties make it easy to organize the tools and materials you use every day. Choose the shorter lengths for small diameter loads, longer lengths and lock hooks for heavier, large loads. Wrap the tie around whatever you've got, slide the locking ratchet on the belt and cinch it up snugly. Swivel hooks make hanging fool-proof.

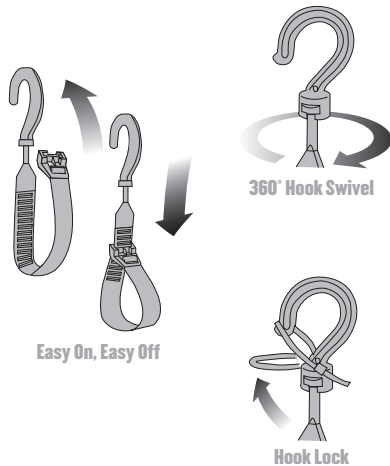


	<p>SHORT Length: 11.8" (30cm) Max Loop Diameter: 1.2"-2.8" (30-70mm)</p> <p>Available With: Small Hook, Large Hook, Large Locking Hook</p>
	<p>MEDIUM Length: 15.8" (40cm) Max Loop Diameter: 1.2"-3.9" (30-100mm)</p> <p>Available With: Small Hook, Large Hook, Large Locking Hook, Hand Grip, Double Belt</p>
	<p>LONG Length: 19.7" (50cm) Max Loop Diameter: 1.2"-5.5" (30-140mm)</p> <p>Available With: Small Hook, Large Hook, Large Locking Hook, Hand Grip, Double Belt</p>

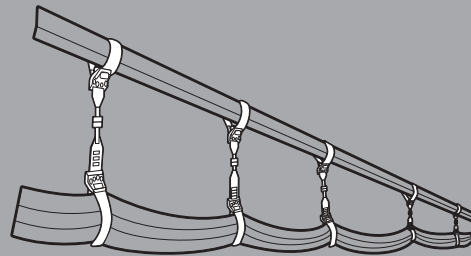

Cable/Wiring Festooning

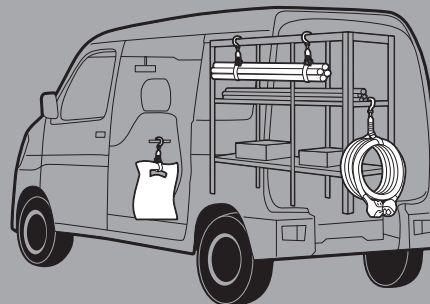

Cargo Organization

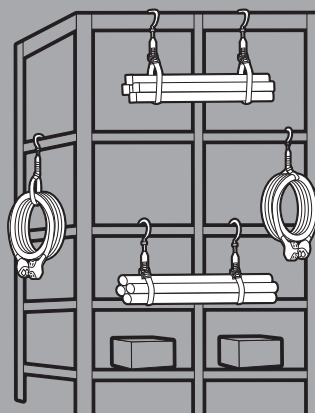

Worksite Organization

1,001 TIE HOOK USES

- Hydraulic Hoses
- Raceway/Cable Tray Assembly
- Cables
- Pneumatic Hoses
- Ropes
- Extension Cords
- Jumper Cables
- Aerial Buckets
- Tool Bags
- Equipment Bags
- Hoses
- Plastic Conduit
- Outdoor Recreation
- Rebar
- PPE
- Gloves
- Cargo
- Wire Festooning
- PVC Pipe
- Lumber
- Riot Response
- And Hundreds More...