


Datasheet
Stock No:1706931

RS Pro
STRAIGHT SMPM PLUG FULL DETENT-1.85mm PLUG ADAPTER

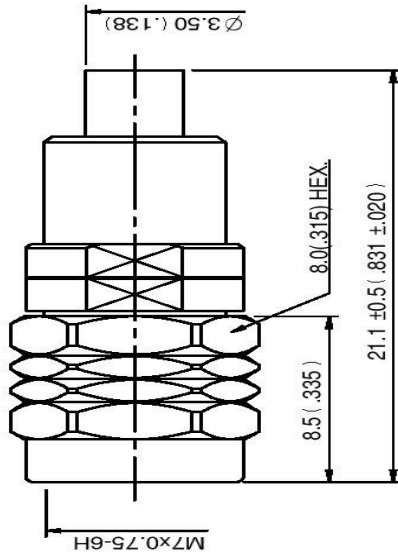

1.0 ELECTRICAL

- 1.1 FREQUENCY RANGE: DC-65 GHz
- 1.2 NOMINAL IMPEDANCE: 50 OHMS
- 1.3 VOLTAGE RATING: 150 VOLTS MAX.
- 1.4 VSWR: 1.25 MAX.

2.0 MATERIALS

- 2.1 BODIES: STAINLESS STEEL PER JIS SUS 303
- 2.2 CENTER CONTACT: BERYLLIUM COPPER PER ASTM B196 UNS C17300

3.0 FINISHES AND OTHERS

- 3.1 SEE BELOW TABLE FOR DETAILS

4.0 MECHANICAL

- 4.1 INTERFACE IN ACCORDANCE WITH: MIL-STD-348B
IEEE-STD 287
- 4.2 RECOMMENDED COUPLING TORQUE: 7 TO 10 in-lbs

5.0 ENVIRONMENTAL

- 5.1 OPERATING TEMPERATURE RANGE: -55° C TO +165° C

APPROVED by _____ DATE: _____

DESCRIPTION		STRAIGHT SMPM PLUG FULL DETENT - 1.85mm PLUG ADAPTER									
7	INSULATION	ULTEM 1000	1	NONE	品名	40650906600001	日	DATE	版	REV.	
6	CRASSIS	STAINLESS STEEL	1	PASSIVATED	TITLE	ROHS COMPLIANT	(50 Ω)	日期	11.22.17	次	A-0
5	CENTER CONTACT	BERYLLIUM COPPER	1	GOLD 50 μ" MIN.	UNIT			DWG.NO.	65-0001-Z		
4	BODY	STAINLESS STEEL	1	PASSIVATED	SCALE						
3	INSULATION	ULTEM 1000	1	NONE	ANGLE	± 5°					
2	WASHER	STAINLESS STEEL	1	NONE	例	4:1					
1	SHELL	STAINLESS STEEL	1	PASSIVATED							
NO	DESCRIPTION	MATERIAL	QTY	FINISH							