



ENGLISH

## Square Polyurethane Rubber Feet

Sticky Feet self-adhesive bumpers are made from 100% polyurethane which outperforms other materials like felt, foam, silicone or plastics. Our polyurethane does not contain any fillers, oils or plasticizers and thus these rubber feet will not stain, mar or scratch any surface. The high performance adhesive backing has a “quick peel” lining for effortless application.

Purpose built to help prevent against slamming, scuffing, vibration and noise. Suitable for use as:

Feet - on the bottom of small house hold appliances or small electrical devices



Stops - for cupboard or cabinet doors and drawers

Spacers - for when assembling other items or to keep gaps between items


Protectors - to help prevent against damage when in transport

### Main features:


- 100% moulded polyurethane
- Superior abrasion resistance, vibration and shock dampening
- Easy “Peel-Off” application, non-staining, non-skidding, and non-marking
- Can be used on wide variety of substrates like plastics, laminates, finished wood, glass, metal, ceramics, painted surfaces, paper etc

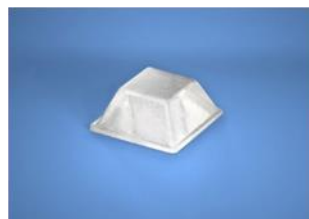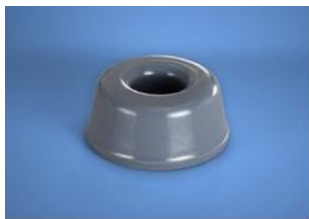

Square Polyurethane Rubber Feet - These square flat-topped bumper pads have a tapered look that provide the largest surface contact area of any of our products. These feet are often used on the bottom of a product to keep them stable and prevent surface damage.

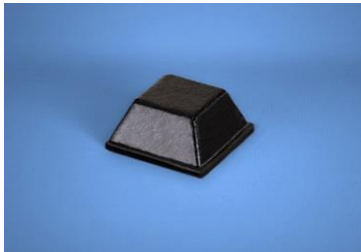

H = Height  
D = Diameter

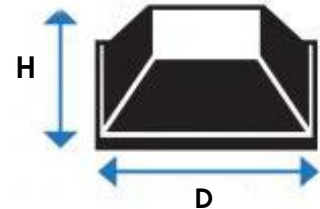

RS Code	Part Number	Description	H (mm)	D (mm)	Colour	Pieces per pad/ layout
1735947	FSQ613-BL-100	Black Square Polyurethane Rubber feet, 5.8mm H x 12.7mm Dia	5.8	12.7	Black	100
1735949	FSQ613-GY-100	Grey Square Polyurethane Rubber feet, 5.8mm H x 12.7mm Dia	5.8	12.7	Grey	100
1735957	FSQ821-CL-49	Clear Square Polyurethane Rubber Feet, 7.6mm H x 20.6mm Dia	7.6	20.6	Clear	49
1735948	FSQ821-BL-49	Black Square Polyurethane Rubber Feet, 7.6mm H x 20.6mm Dia	7.6	20.6	Black	49
1735950	FSQ821-GY-49	Grey Square Polyurethane Rubber Feet, 7.6mm H x 20.6mm Dia	7.6	20.6	Grey	49
1735945	FSQ313-BL-100	Black Square Polyurethane Rubber Feet, 3mm H x 12.7mm Dia	3	12.7	Black	100
1735946	FSQ313-GY-100	Grey Square Polyurethane Rubber Feet, 3mm H x 12.7mm Dia	3	12.7	Grey	100

TEST METHOD	STANDARD DUROMETER
Tensile Strength Mpa	4
Elongation, %	192
Tear Strength (kg/cm)	38
Hardness, Shore A	60 — 70
Bashore Rebound, %	27
Abrasion Resistance g/1000 cycles Tabor H18, 1kg	0.016
QUV (500 hours)	Slight Yellowing
TYPICAL PROPERTIES	
Static Shear Test	300+ hours (ASTM B 3654)
Quick Tack-Stainless Steel	633 g/cm <sup>2</sup>
Peel Adhesion	1.7kg/cm (ASTM D 3330)
Substrate:	
Thickness	50 microns
Basis Weight	14 m <sup>2</sup> /kg
Tensile Strength	190 MPa
Liner:	
Thickness	158 microns
Basis Weight	151 g/m <sup>2</sup>
Temperature:	
Application	18°C — 65.6°C
End Use	-40°C — 149°C
Substrate Elongation	120% MD
Shelf Life	24 months based on accelerated aging
Storage	73.4°F (23°C) and 55% relative humidity