


RS Part Number: **466-132**  
 Specifications and dimensions

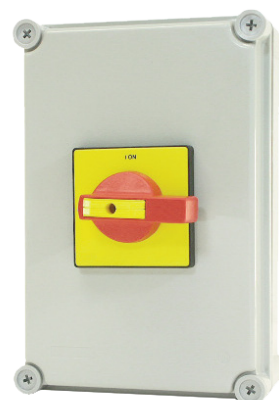

- Boxed isolator 4 pole
- ABS plastic enclosure with padlockable handle

Specifications	
Height	280 mm
Width	190 mm
Depth	130 mm
Depth including switch	190 mm
Degree of protection	IP65
Rated operational current Ie AC21A	125 A
Rated operational current Ie AC22A	125 A
Rated operational voltage Ue IEC & EN	690 V
Rated operational power AC23A 380-440V	75 kW
Rated operational power AC3 440V	55 kW
Maximum gL fuse size IEC	125 A
Rated fused short circuit capacity IEC	30 kA
Knockout size	25 mm
Normal operating temperature	-25°C to +40°C
Maximum cable capacity	50 mm <sup>2</sup>
Recommended tightening torque	2.5 Nm
Number of possible auxilliary contacts	None