

71 01 160

KNIPEX CoBolt® S Compact Bolt Cutters



- Specially suitable for small hands
- Precision cutting edges for soft and hard wire as well as piano wire
- Cuts components such as bolts, nails, rivets etc. up to Ø 4.4 mm
- Most efficient joint design ensures exceptional cutting performance with little effort
- Cutting edges additionally induction hardened, cutting edge hardness approx. 64 HRC
- The microstructure on cutters keeps the material to be cut in a good insertion position: makes optimal use of the mechanics
- With gripping surface below the joint for gripping and pulling wires with a diameter as from 1.0 mm
- Chrome vanadium heavy-duty steel, forged, multi stage oil-hardened


60 % less effort required compared to conventional high-leverage diagonal cutters

The ingenious lever action mechanism guarantees an extremely favourable lever ratio with very low friction. Manual force is reinforced up to 30 times


Article No.	71 01 160
EAN	4003773082668
Style	
Pliers	black atramentized
Handles	plastic coated
Cutting capacities medium hard wire (diameter) Ø mm	4,4
Cutting capacities hard wire (diameter) Ø mm	3,2
Cutting capacities piano wire (diameter) Ø mm	3,0
Cutting capacities soft wire (diameter) Ø mm	5,3
Length mm	160
Net weight g	195



Powerful through to the tips

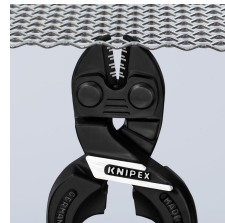

Slim head for ideal accessibility

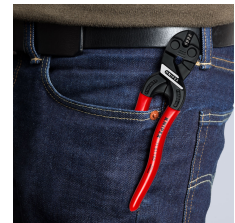

Compact, light and always to hand

technical change and errors excepted