

Stanilite®

Platinum Spitfire® LED surface mount non-maintained

p-Range



Range

Platinum range

Product group


Spitfire LED



Features

- 5 year warranty
- Superior photometric classification
- LED technology 100,000 hours plus lamp life
- Single or dual LED option
- Low power consumption and LED light source for reduced operation and maintenance costs
- Advance charging technology combined with Lithium iron phosphate battery for long life and low maintenance
- Surface mount
- Low maintenance - ideal for factories and warehouses

Catalogue no.	Description
Standard products	
SFB1LEDP	Platinum Spitfire single LED surface mount
SFB2LEDP	Platinum Spitfire dual LED surface mount
Spare parts	
03-01301P	Battery LiFePO4 3.2V 3.2Ah (suits single LED)
03-01303P	Battery LiFePO4 3.2V 4.5Ah (suits dual LED)

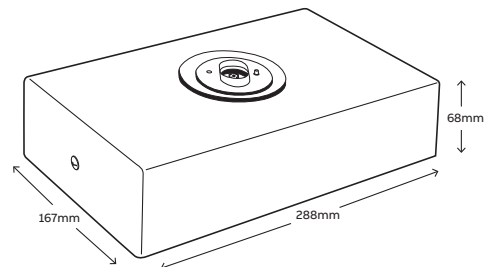

Dimensions		
Length	Width	Height
288mm	167mm	68mm
Weight		
Model	Weight	
Standard	2.2kg	
Construction		
Part	Construction	
Lamp head	White polycarbonate	
Surface mount box	White powder coated steel	

Light source		
	Model	Light source
	Single LED	2W
	Dual LED	3W

Power consumption		
	Model	Power consumption
	Standard	1.0W

Note: Preliminary results

Photometrics			
	Model	Class	Classification
	Single LED	C0	D40
		C90	D40
	Dual LED	C0	D63
		C90	D63

Note:

- Designed to comply with AS2293 and meet relevant Australian EMC standards