

## Desk-Mount Dual Monitor Arm - Articulating


Product ID: ARMDUAL



The ARMDUAL Articulating Dual-Monitor Arm lets you mount two displays to your desk or table, with extension, tilt, pan, swivel, pivot and height adjustments.

The desk-mount monitor arm offers a wide range of motion on several axes, giving you the freedom to place your displays side-by-side, spread apart, back-to-back or anywhere in between. For viewing longer pages or blocks of code without scrolling, the dual arm also supports landscape to portrait display rotation for either monitor.

Mounting your displays on a dual monitor arm above the desk surface enables you to adjust your display height, position and viewing angles easily for an ergonomic work environment, with the added benefit of reclaiming valuable workspace on your desk.

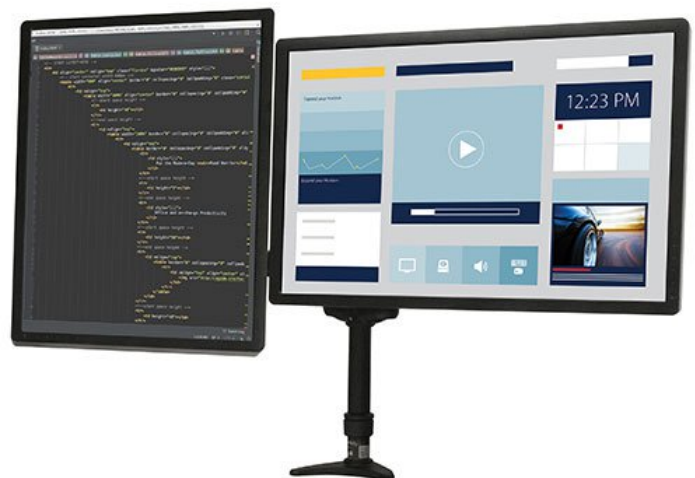

Supporting 12 - 24" displays up to a maximum weight capacity of 30lbs (13.6kg) per arm, the dual arm monitor mount holds your displays with ease, and integrates a cable management channel to keep things neat. For added installation flexibility, the included mounting hardware can either clamp to the side of your desk / table or mount through a grommet hole, for a versatile dual-monitor mounting solution.

Backed by a StarTech.com 5-year warranty and free, lifetime technical support.

### Certifications, Reports and Compatibility



### Applications

- Mount dual displays to the side of your desk or table with a wide range of adjustment capability
- Grommet mount your displays through a desk or above a server cabinet and position as you need them
- Spread displays apart or position them back-to-back for multi-user workstations
- Rotate displays to portrait orientation for web design and coding

### Features

- Dual articulating arms for a wide range of motion
- Supports displays from 12 to 24" (30lbs / 13.6kg capacity)
- 360° rotation around the support post and at the elbow
- 180° rotation at the shoulder
- +/-90° Tilt and +/-90° Pan
- Maximum arm extension of 17.5in (445mm)
- Landscape to portrait screen rotation
- Includes convertible desk / grommet mount clamp
- Desk clamp fits desks up to 2.95in (75mm) thick, grommet clamp fits up to 3.74in (95mm)
- Integrated cable management

<b>Hardware</b>	Warranty	5 Years
	# of Displays Supported	2
	Articulating	Yes
	Mounting Options	Desk & Grommet Clamp
	VESA Hole Pattern(s)	75x75 mm 100x100 mm
	Wallmountable	No
<b>Performance</b>	Display Rotation	360°
	Height Adjustment	Yes
	Maximum Arm Extension	17.5 in [445 mm]
	Maximum Display Size	24in
	Mounting Surface Thickness	Desk Clamp: Table Thickness 0.39 - 2.95 in. (10 - 75 mm) Grommet Clamp: Table Thickness 0.39 - 2.95 in. (10 - 75 mm) Table Hole for Grommet Mount: 0.39 - 2.75 in. (10 - 70 mm)
	Pan	+/- 90°
	Swivel / Pivot	360° around the support post 180° at the shoulder 360° at the elbow
	Tilt	+/- 90°
	Weight Capacity (Per Display)	30 lb [13.6 kg]
<b>Physical Characteristics</b>	Color	Black
	Enclosure Type	Steel and Plastic
	Product Height	0.000
	Product Length	0.000
	Product Weight	8.9 lb [4 kg]
	Product Width	0.000
<b>Packaging Information</b>	Shipping (Package) Weight	10.8 lb [4.9 kg]
<b>What's in the Box</b>	Included in Package	2 - Articulating LCD Arms 1 - Desk Clamp 1 - Grommet Plate 1 - DEK

- 2 - Cover Plates
- 8 - Spacers
- 8 - M4x12mm Phillips Screws
- 8 - M4x25mm Phillips Screws
- 2 - M6x12mm Phillips Screws
- 2 - M6 Washers
- 2 - Cable Clip
- 4 - Plastic Gasket Cushions
- 1 - 2.5mm Allen Wrench
- 1 - 4mm Allen Wrench
- 1 - 6mm Allen Wrench
- 1 - Instruction Manual

---

Product appearance and specifications are subject to change without notice.