

MICRO-TECH® "HIGH CAPACITY" CUTTERS: POWER




Standards :


NF ISO 9654, ISO 9654, DIN ISO 9654, ASME B107.500

Description :

- These pliers are suited to major efforts and repetitive work over a broad range of materials.
- Fall prevention models avoid wire ejection.

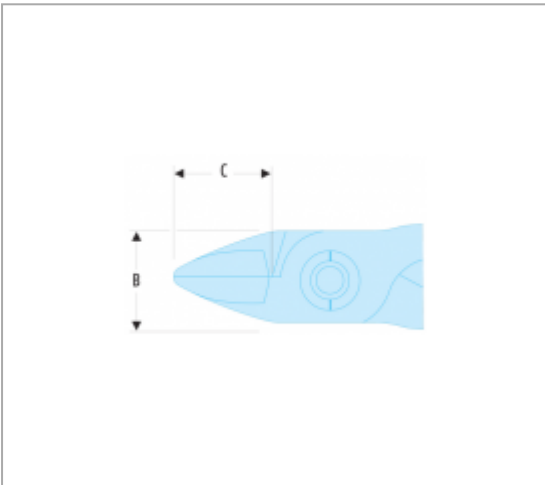

References :

	B [MM]	C [MM]	E [MM]	L [M]	L [MM]	CUT	CU - NI Ø [MM]	FE 30 HRC DIAM. [MM]	PIANO DIAMETER [MM]	[G]
415.MT	16	16	8	125	125	H	0,3 - 2,0	0,9	-	95
405.12MT	16	16	8	125	125	h	0,4 - 2,0	1,0	0,8	95