

406.RMT | MICRO-TECH® "COMPACT" CUTTERS: HANDLING




Norm :

NF ISO 9654, ISO 9654, DIN ISO 9654, ASME B107.500


Description :

- These pliers combine cutting performance with accessibility thanks to their new slim diagonal shape.
- Fall prevention models avoid wire ejection. The 405.MT pliers allow to cut piano wire up to 0.4 mm.

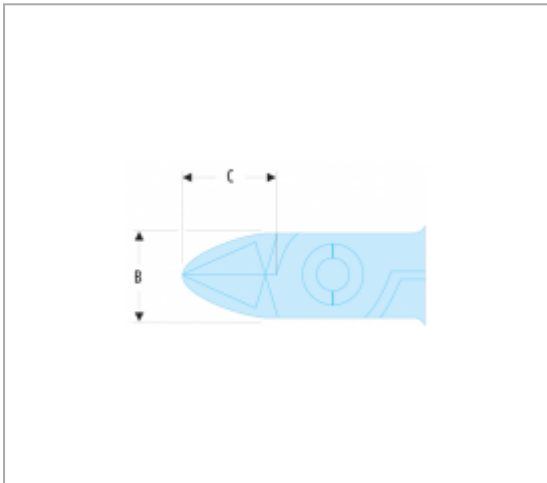

Informations :

	406.RMT
B [mm]	10,5
C [mm]	9,5
E [mm]	7
L [mm]	110
Cut	H
Cu - Ni Ø [mm]	0,1 - 1,1
Bits	212.E35
Fe 30 HRc diam. [mm]	0,6

	406.RMT
Piano Diameter [mm]	-
Offcut retainer	•
[g]	60