

249.4 | 249 - STANDARD DRIFT PUNCHES




Norm :


NF E 71-211, DIN 6450, ASME B107.410

Description :

- Hexagonal shank, high-strength steel tip, hardened to 53-58 HRc.
- Zinc-plated finish.

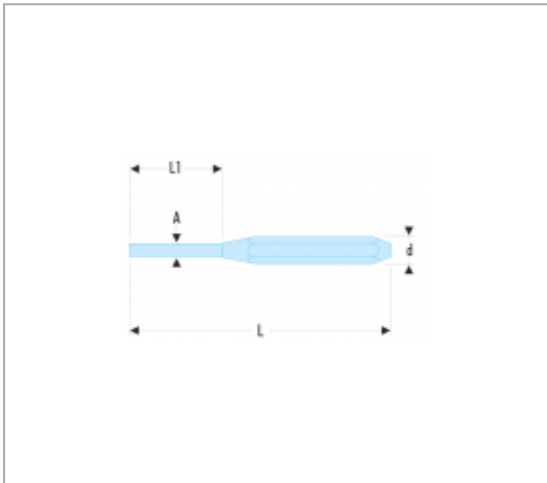

Informations :

	249.4
A [mm]	3,9
d [mm]	10
L [mm]	150
L1 [mm]	50
[g]	65